


Technical data sheet

Rung CK 40

Item number: 6008240

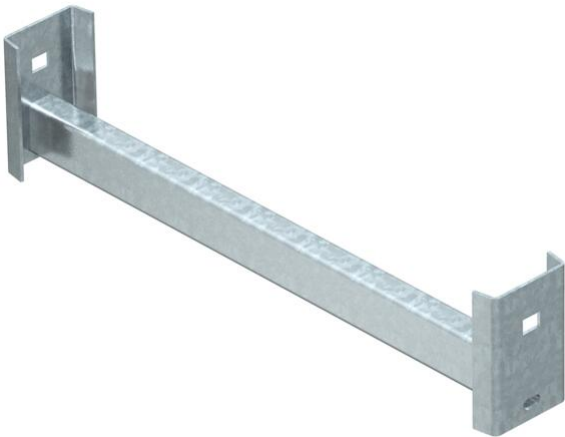

CK40 rung for use in heavy-duty vertical ladders and in IS 8 supports.
The maximum rung load is 175 kg.



- St** Steel
- FT** Hot-dip galvanised

Master data		
Item number	6008240	
Description 1	C-frame	
Description 2	for IS 8 support	
Manufacturer	OBO	
Dimension	B354mm	
Colour	zinc	
Material	Steel	
Surface	Hot-dip galvanised	
Surface standard	DIN EN ISO 1461	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	95.5 kg	
Weight unit	kg/100 pc.	


Technical data sheet

Rung CK 40

Item number: 6008240



Dimensions

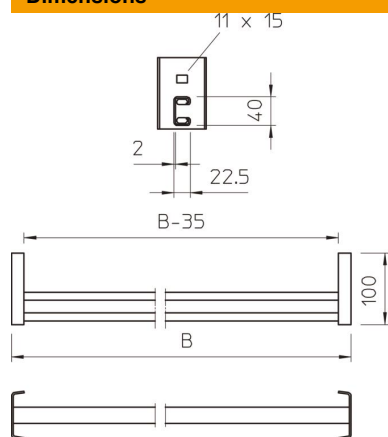

lampDimension WxH	40 x 22,5 mm
Length	354 mm
Width	354 mm
Height	100 mm

Technical data

Material thickness	2 mm
Slot width	18 mm