


# Technical data sheet

Profile rail, 17 mm slot, perforated, black

Item number: 1104293



Middle C profile rail for cable routing, in connection with clamp clips with hammer-head foot Can also be used as a suspended construction for cable tray systems.

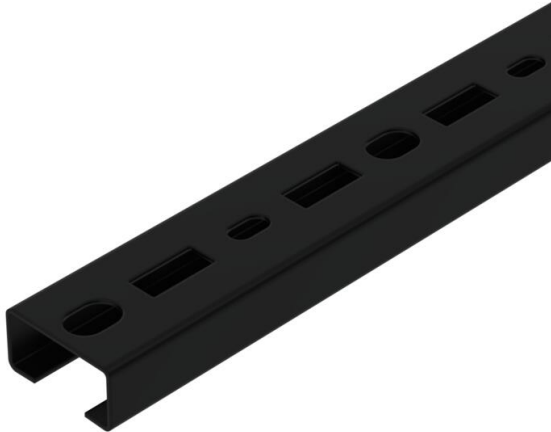


St	Steel
P135	PES135 - Polyester

## Master data

 Item number	1104293
Type	CML3518P0400 SW
Description 1	Profile rail
Description 2	perforated, slot 17mm
Manufacturer	OBO
Dimension	400x35x18
Colour	Jet black; RAL 9005
Material	Steel
Surface	PES135 - Polyester
Surface standard	
Smallest sales unit	10
Unit of quantity	Piece
Weight	30 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,7256 kg CO2e / 1 Piece

Item number: 1104293



Breakable	no
Type of perforation	Perforated back
Version for	Single profile
Drill hole spacing, centre	25 mm
Maintain electrical functions	yes
Material thickness	1.25 mm
With perforation	yes
With toothing	no
Profile shape	C profile
Rustproof steel, pickled	no
Slot width	17 mm
Static value Iy	0.41 cm
Static value Iz	1.81 cm
Static value Wy	0.41 cm <sup>2</sup>
Static value Wz	1.03 cm <sup>2</sup>