

# Technical data sheet

CML3518 profile rail, slot 17 mm, FS, perforated

Item number: 1104315



Light-duty profile rail, perforated, slot width 17 mm.



- St Steel
- FS Strip galvanized

| Master data                        |                         |  |
|------------------------------------|-------------------------|--|
| Item number                        | 1104315                 |  |
| Type                               | CML3518P0700FS          |  |
| Description 1                      | Profile rail            |  |
| Description 2                      | perforated, slot 17mm   |  |
| Manufacturer                       | OBO                     |  |
| Dimension                          | 700x35x18               |  |
| Material                           | Steel                   |  |
| Surface                            | Strip galvanized        |  |
| Surface standard                   | DIN EN 10346            |  |
| Smallest sales unit                | 10                      |  |
| Unit of quantity                   | Piece                   |  |
| Weight                             | 49.7 kg                 |  |
| Weight unit                        | kg/100 pc.              |  |
| CO2 Footprint (GWP) Cradle-to-Gate | 1,2294 kg COe / 1 Piece |  |


# Technical data sheet

CML3518 profile rail, slot 17 mm, FS, perforated

Item number: 1104315



## Dimensions

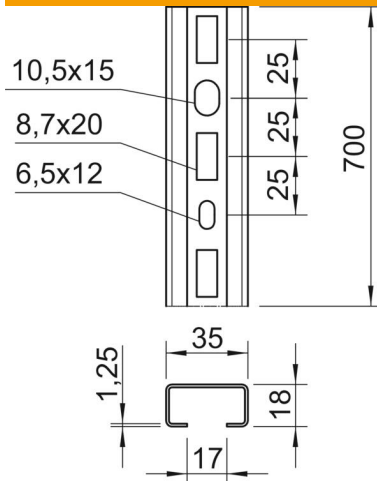

|             |        |
|-------------|--------|
| Length      | 700 mm |
| Width       | 35 mm  |
| Height      | 18 mm  |
| Dimension L | 700 mm |

## Technical data

|                               |                      |
|-------------------------------|----------------------|
| Breakable                     | no                   |
| Type of perforation           | Perforated back      |
| Version for                   | Single profile       |
| Drill hole spacing, centre    | 25 mm                |
| Maintain electrical functions | yes                  |
| Material thickness            | 1.25 mm              |
| With perforation              | yes                  |
| With tothing                  | no                   |
| Profile shape                 | C profile            |
| Rustproof steel, pickled      | no                   |
| Slot width                    | 17 mm                |
| Static value A                | 0.88 cm <sup>2</sup> |
| Static value I <sub>y</sub>   | 0.41 cm              |
| Static value I <sub>z</sub>   | 1.81 cm              |
| Static value W <sub>y</sub>   | 0.41 cm <sup>2</sup> |
| Static value W <sub>z</sub>   | 1.03 cm <sup>2</sup> |