

Technical data sheet

PYROCOMB® Intube half shell

Item number: 7204306



Internally coated half shell, the inner space of which can be fully assigned with cables and electrical installation pipes. For interior application. CE-labelled, European approved construction product according to ETA-13/0904 and German general type approval. Fire resistance up to 120 minutes.

Closing with foam plug included in the delivery. The surface seal is created with PYROCOAT® ASX coating. The system is particularly suitable for underfloor areas.

Details can be found in the mounting instructions/approval.



PVC Polyvinylchloride

Master data

| | |
|---------------------|-------------------|
| Item number | 7204306 |
| Description 1 | Half-shell |
| Description 2 | internally coated |
| Manufacturer | OBO |
| Dimension | 200x116x65mm |
| Colour | Grey |
| Material | Polyvinylchloride |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 20 kg |
| Weight unit | kg/100 pc. |


Technical data sheet

PYROCOMB® Intube half shell




Item number: 7204306

Dimensions

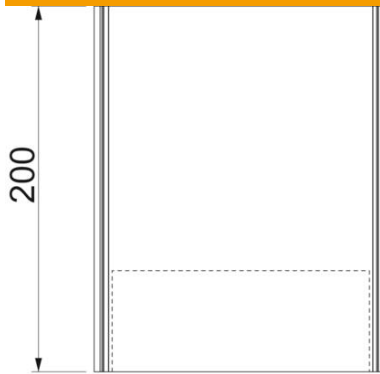

| | |
|------------------|--------|
| Length | 200 mm |
| Dimension B | 118 mm |
| Dimension d min. | 106 mm |
| Dimension L | 200 mm |

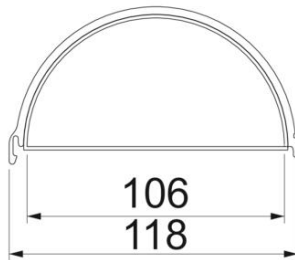

Technical data

| | |
|-------------------------|---------------|
| Fire protection version | Miscellaneous |
| Shape | Round |
| For opening, max. | 165 mm |
| For opening, min. | 125 mm |
| Accessories required | no |