

# Technical data sheet

## Pluggable cover, equipped, OBO GST18

Item number: 2006060



Pluggable cover for the closing of junction boxes, equipped with 6 Wielland GST18 plug systems, prewired with lever plug-in connector With quick lock in cover, sealable. Halogen-free material, UV-resistant Flame-resistant to DIN EN 60695/2/11, test temperature 650 °C. Impact resistance IK07 at room temperature. Protection class IP30.



**PP** Polypropylene

### Master data

|                     |                            |
|---------------------|----------------------------|
| Item number         | 2006060                    |
| Type                | D01 6x3p WD(4+2)           |
| Description 1       | Plug-in cover              |
| Description 2       | for junction box, equipped |
| Manufacturer        | OBO                        |
| Dimension           | 150x116x60                 |
| Colour              | Light grey; RAL 7035       |
| Material            | Polypropylene              |
| Smallest sales unit | 1                          |
| Unit of quantity    | Piece                      |
| Weight              | 22.5 kg                    |
| Weight unit         | kg/100 pc.                 |


# Technical data sheet

Pluggable cover, equipped, OBO GST18

Item number: 2006060



## Dimensions

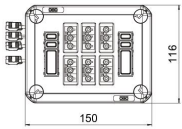

|        |        |
|--------|--------|
| Length | 150 mm |
| Width  | 116 mm |
| Height | 60 mm  |

## Technical data

|                                          |                                                        |
|------------------------------------------|--------------------------------------------------------|
| Number of 3-pole sockets                 | 6                                                      |
| Number of 4-pole sockets                 | 0                                                      |
| Number of 5-pole sockets                 | 0                                                      |
| Version, concealed and cavity wall cover | Suitable for snap-in connector (manufacturer specific) |
| Fastening type                           | Screw fastening                                        |
| Shape                                    | Rectangular                                            |
| Halogen-free                             | yes                                                    |
| Protection rating                        | IP30                                                   |