

Technical data sheet

Pluggable cover, unequipped

Item number: 2006040



Pluggable cover for the closing of junction boxes, equipped with 8 break-out openings for connection sockets by Wieland and Wago, 3- to 5-pole With quick lock in cover, sealable. Halogen-free material, UV-resistant Flame-resistant to DIN EN 60695/2/11, test temperature 650 °C. Impact resistance IK07 at room temperature. Protection class IP30.



Flame icon



650°C



CE



IP 30



500 V

PP

Polypropylene

| Master data | | |
|---------------------|------------------------------|--|
| Item number | 2006040 | |
| Description 1 | Plug-in cover | |
| Description 2 | for junction box, unequipped | |
| Manufacturer | OBO | |
| Dimension | 150x116x39 | |
| Colour | Light grey; RAL 7035 | |
| Material | Polypropylene | |
| Smallest sales unit | 1 | |
| Unit of quantity | Piece | |
| Weight | 8.042 kg | |
| Weight unit | kg/100 pc. | |


Technical data sheet

Pluggable cover, unequipped

Item number: 2006040



Dimensions

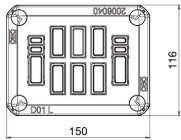

| | |
|--------|--------|
| Length | 150 mm |
| Width | 116 mm |
| Height | 39 mm |

Technical data

| | |
|------------------------------------------|-----------------|
| Expandable | no |
| Version, concealed and cavity wall cover | Mounting lid |
| Fastening type | Screw fastening |
| Shape | Rectangular |
| For Ex zone | Without |
| For Ex zone gas | Without |
| For Ex zone dust | Without |
| Halogen-free | yes |
| With connection cable | no |
| Protection rating | IP30 |