

Technical data sheet

Pluggable cover, equipped, OBO WINSTA MIDI

Item number: 2006096



Pluggable cover for the closing of junction boxes, equipped with 2 Wago WINSTA MIDI plug systems, prewired with lever plug-in connector With quick lock in cover, sealable. Halogen-free material, UV-resistant Flame-resistant to DIN EN 60695/2/11, test temperature 650 °C. Impact resistance IK07 at room temperature. Protection class IP30.



PP Polypropylene

Master data

| | |
|---------------------|----------------------------|
| Item number | 2006096 |
| Type | D02 2x5p DALI WG |
| Description 1 | Plug-in cover |
| Description 2 | for junction box, equipped |
| Manufacturer | OBO |
| Dimension | 150x116x60 |
| Colour | Light grey; RAL 7035 |
| Material | Polypropylene |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 12.9 kg |
| Weight unit | kg/100 pc. |


Technical data sheet

Pluggable cover, equipped, OBO WINSTA MIDI

Item number: 2006096



Dimensions

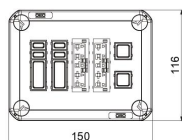

| | |
|--------|--------|
| Length | 150 mm |
| Width | 116 mm |
| Height | 60 mm |

Technical data

| | |
|------------------------------------------|--------------------------------------------------------|
| Number of 3-pole sockets | 0 |
| Number of 4-pole sockets | 0 |
| Number of 5-pole sockets | 2 |
| Version, concealed and cavity wall cover | Suitable for snap-in connector (manufacturer specific) |
| Fastening type | Screw fastening |
| Shape | Rectangular |
| Halogen-free | yes |
| Protection rating | IP30 |