

# Technical data sheet

## Pluggable cover, equipped, OBO GST18

Item number: 2006088



Pluggable cover for the closing of junction boxes, equipped with 4 Wieland GST18 plug systems, prewired with lever plug-in connectors. With quick lock in cover, sealable. Halogen-free material, UV-resistant Flame-resistant to DIN EN 60695/2/11, test temperature 650 °C. Impact resistance IK07 at room temperature. Protection rating IP30



**PP** Polypropylene

### Master data

Item number	2006088
Type	D02 4x5p WD
Description 1	Plug-in cover
Description 2	for junction box, equipped
Manufacturer	OBO
Dimension	150x116x60
Colour	Light grey; RAL 7035
Material	Polypropylene
Smallest sales unit	1
Unit of quantity	Piece
Weight	24.7 kg
Weight unit	kg/100 pc.


# Technical data sheet

Pluggable cover, equipped, OBO GST18

Item number: 2006088



## Dimensions

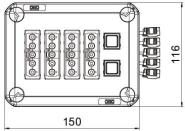

Length	150 mm
Width	116 mm
Height	60 mm

## Technical data

Number of 3-pole sockets	0
Number of 4-pole sockets	0
Number of 5-pole sockets	4
Version, concealed and cavity wall cover	Suitable for snap-in connector (manufacturer specific)
Fastening type	Screw fastening
Shape	Rectangular
Halogen-free	yes
Protection rating	IP30