

Technical data sheet

Pluggable cover, unequipped

Item number: 2006080



Pluggable cover for the closing of junction boxes, equipped with 6 break-out openings for connection sockets by Wieland and Wago, 3- to 5-pole. With quick lock in cover, sealable. Halogen-free material, UV-resistant Flame-resistant to DIN EN 60695/2/11, test temperature 650 °C. Impact resistance IK07 at room temperature. Protection class IP30.



PP Polypropylene

Master data

Item number	2006080
Type	D02 L
Description 1	Plug-in cover
Description 2	for junction box, unequipped
Manufacturer	OBO
Dimension	150x116x39
Colour	Light grey; RAL 7035
Material	Polypropylene
Smallest sales unit	1
Unit of quantity	Piece
Weight	8.27 kg
Weight unit	kg/100 pc.


Technical data sheet

Pluggable cover, unequipped

Item number: 2006080



Dimensions

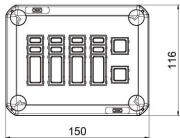

Length	150 mm
Width	116 mm
Height	39 mm

Technical data

Version, concealed and cavity wall cover	Suitable for snap-in connector (manufacturer specific)
Fastening type	Screw fastening
Shape	Rectangular
For Ex zone	Without
For Ex zone gas	Without
For Ex zone dust	Without
Halogen-free	yes
Protection rating	IP30