

# Technical data sheet

## Pluggable cover, equipped, Modul 45

Item number: 2006116



Pluggable cover for the closing of junction boxes, equipped with 2 Module 45 sockets, prewired with lever plug-in connector With quick lock in cover, sealable. Halogen-free material, UV-resistant Flame-resistant to DIN EN 60695/2/11, test temperature 650 °C. Impact resistance IK07 at room temperature. Protection class IP30.





500  
V

IP  
30

PP

Polypropylene

| Master data         |                            |
|---------------------|----------------------------|
| Item number         | 2006116                    |
| Type                | D03 2MSD WS                |
| Description 1       | Plug-in cover              |
| Description 2       | for junction box, equipped |
| Manufacturer        | OBO                        |
| Dimension           | 150x116x60                 |
| Colour              | Light grey; RAL 7035       |
| Material            | Polypropylene              |
| Smallest sales unit | 1                          |
| Unit of quantity    | Piece                      |
| Weight              | 19.4 kg                    |
| Weight unit         | kg/100 pc.                 |


# Technical data sheet

## Pluggable cover, equipped, Modul 45

Item number: 2006116



### Dimensions

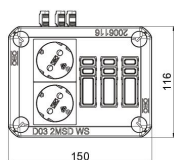

|        |        |
|--------|--------|
| Length | 150 mm |
| Width  | 116 mm |
| Height | 60 mm  |

### Technical data

|                                          |                  |
|------------------------------------------|------------------|
| Version, concealed and cavity wall cover | Lid with sockets |
| Fastening type                           | Screw fastening  |
| Shape                                    | Rectangular      |
| Halogen-free                             | yes              |
| Protection rating                        | IP30             |