

Technical data sheet

Pluggable cover, unequipped

Item number: 2006130



Pluggable cover for the closing of junction boxes, equipped with 8 break-out openings for DATA systems based on Keystone. With quick lock in cover, sealable. Halogen-free material, UV-resistant Flame-resistant to DIN EN 60695/2/11, test temperature 650 °C. Impact resistance IK07 at room temperature. Protection class IP30.



Flame icon



650°C



CE



IP 30



500 V

PP

Polypropylene

Master data	
Item number	2006130
Type	D04 L
Description 1	Plug-in cover
Description 2	for junction box, unequipped
Manufacturer	OBO
Dimension	150x116x39
Colour	Light grey; RAL 7035
Material	Polypropylene
Smallest sales unit	1
Unit of quantity	Piece
Weight	8.321 kg
Weight unit	kg/100 pc.


Technical data sheet

Pluggable cover, unequipped

Item number: 2006130



Dimensions

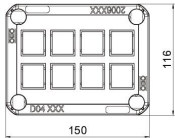

Length	150 mm
Width	116 mm
Height	39 mm

Technical data

Version, concealed and cavity wall cover	Suitable for data link
Fastening type	Screw fastening
Shape	Rectangular
For Ex zone	Without
For Ex zone gas	Without
For Ex zone dust	Without
Halogen-free	yes
Protection rating	IP30