

Technical data sheet

Pluggable cover, unequipped

Item number: 2006136



Pluggable cover for the closing of junction boxes, equipped with break-out openings for multiple-pole systems or DATA systems based on Keystone. With quick lock in cover, sealable. Halogen-free material, UV-resistant Flame-resistant to DIN EN 60695/2/11, test temperature 650 °C. Impact resistance IK07 at room temperature. Protection rating IP30



PC Polycarbonate

Master data

Item number	2006136
Type	D05
Description 1	Plug-in cover, elevated
Description 2	for junction box
Manufacturer	OBO
Dimension	150x116x39
Colour	Light grey; RAL 7035
Material	Polycarbonate
Smallest sales unit	1
Unit of quantity	Piece
Weight	10.64 kg
Weight unit	kg/100 pc.


Technical data sheet

Pluggable cover, unequipped

Item number: 2006136



Dimensions

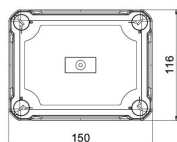

Length	150 mm
Width	116 mm
Height	39 mm

Technical data

Version, concealed and cavity wall cover	Blanking lid
Fastening type	Screw fastening
Shape	Rectangular
With connection cable	no
Protection rating	IP66