


Technical data sheet

Cover for single accessory mounting box for WDK trunking, trunking height 110 mm
Item number: 6194036

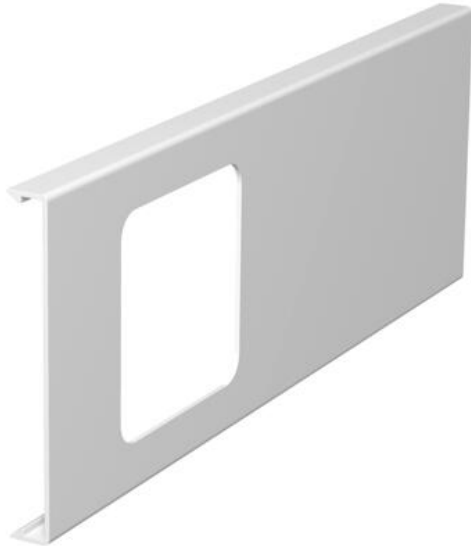

Cover section, single, for device installation in WDK trunking in conjunction with the device installation socket, type 2390.



PVC Polyvinylchloride

Master data


Item number	6194036
Type	D2-1 110RW
Description 1	Cover
Description 2	for single device installation
Manufacturer	OBO
Dimension	110x300mm
Colour	Pure white; RAL 9010
Material	Polyvinylchloride
Smallest sales unit	1
Unit of quantity	Piece
Weight	8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2247 kg CO2e / 1 Piece

Technical data sheet

Cover for single accessory mounting box for WDK trunking, trunking height 110 mm
Item number: 6194036



Dimensions

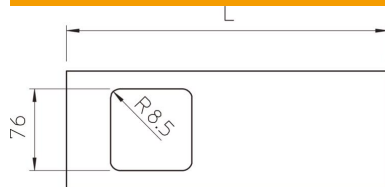

Length	300 mm
Width	109 mm
Height	14 mm

Technical data

Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C