

Technical data sheet

Cover for 90° vertical bend, rising, FT

Item number: 7131710



Cover for all rising vertical bends.

The fastening is guaranteed by the overlap of the cable tray covers. The cover can also be fastened using cover clamps.



St Steel

FT Hot-dip galvanised

Master data

Item number	7131710
Type	DBV 100 S FT
Description 1	Cover for 90° vertical bend
Description 2	rising
Manufacturer	OBO
Dimension	B100mm
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	37.2 kg
Weight unit	kg/100 pc.


Technical data sheet

Cover for 90° vertical bend, rising, FT

Item number: 7131710



Dimensions

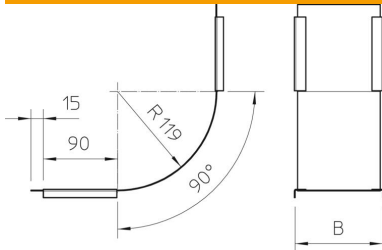

Width	100 mm
Plate thickness	0.75 mm
Dimension B	100 mm

Technical data

Bend (angle)	90°
Fastening type	Cover clamp
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Change of direction	Vertical rising
Rustproof steel, pickled	no
Hinged	no