

Technical data sheet

Cover for 90° vertical bend, rising, FS

Item number: 7130817



Cover for all rising vertical bends.

The fastening is guaranteed by the overlap of the cable tray covers. The cover can also be fastened using cover clamps.



St

Steel

FS

Strip galvanized

Master data

| | |
|-----------------------------------|-----------------------------|
| Item number | 7130817 |
| Type | DBV 300 S FS |
| Description 1 | Cover for 90° vertical bend |
| Description 2 | rising |
| Manufacturer | OBO |
| Dimension | B300mm |
| Colour | zinc |
| Material | Steel |
| Surface | Strip galvanized |
| Surface standard | DIN EN 10346 |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 49 kg |
| Weight unit | kg/100 pc. |
| CO Footprint (GWP) Cradle-to-Gate | 1,7225 kg COe / 1 Piece |


Technical data sheet

Cover for 90° vertical bend, rising, FS

Item number: 7130817



Dimensions

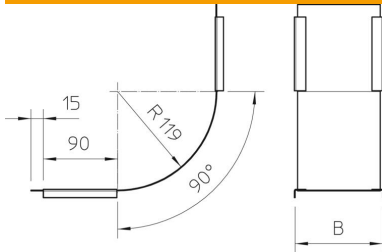

| | |
|-----------------|---------|
| Width | 300 mm |
| Width | 12 in |
| Plate thickness | 0.03 in |
| Plate thickness | 0.75 mm |
| Dimension B | 300 mm |

Technical data

| | |
|-------------------------------|-----------------|
| Bend (angle) | 90° |
| Fastening type | Cover clamp |
| Maintain electrical functions | no |
| Suitable for mesh cable tray | no |
| Suitable for cable ladder | no |
| Suitable for cable tray | yes |
| Change of direction | Vertical rising |
| Rustproof steel, pickled | no |
| Hinged | no |