

Technical data sheet

Cover for 90° vertical bend 60, falling, A4

Item number: 7130972



Cover for falling vertical bends of side height 60 mm.
The fastening is guaranteed by the overlap of the cable tray covers. The cover can also be fastened using cover clamps.



- A4 Stainless steel
- 2B Bright, treated

Master data		
Item number	7130972	
Description 1	Cover for 90° vertical bend	
Description 2	falling	
Manufacturer	OBO	
Dimension	B100mm	
Colour	stainless steel	
Material	Stainless steel	
Surface	Bright, treated	
Surface standard		
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	42.1 kg	
Weight unit	kg/100 pc.	


Technical data sheet

Cover for 90° vertical bend 60, falling, A4

Item number: 7130972



Dimensions

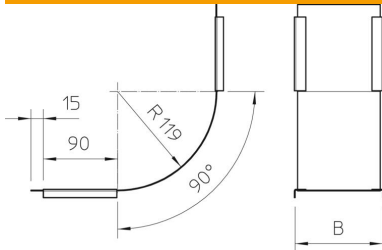

Width	100 mm
Width	4 in
Height	60 mm
Plate thickness	0.03 in
Plate thickness	0.75 mm
Dimension B	100 mm

Technical data

Bend (angle)	90°
Fastening type	Sash lock
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Change of direction	Vertical, falling
Rustproof steel, pickled	no
Hinged	no