

Technical data sheet

Cover for 45° bend FT

Item number: 7132002



Cover for 45° bend with pre-mounted turn buckles.
The cover can be used with fittings of all side heights.




St	Steel
FT	Hot-dip galvanised

Master data

Item number	7132002
Type	DFB 45 100 FT
Description 1	45° bend cover
Description 2	with sash locks, RB 45 100
Manufacturer	OBO
Dimension	B100mm
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	19.4 kg
Weight unit	kg/100 pc.

Dimensions

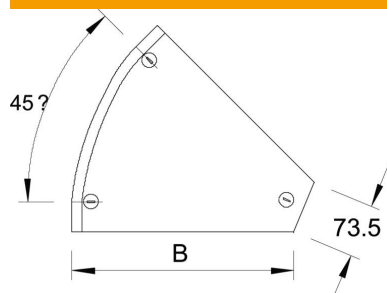

Width	100 mm
Height	35 mm
Plate thickness	1 mm
Dimension B	100 mm

Technical data sheet

Cover for 45° bend FT

Item number: 7132002



Technical data

Bend (angle)	45°
Number of turn buckles	3 St.
Fastening type	Sash lock
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Change of direction	Horizontal
Rustproof steel, pickled	no
Hinged	no