


Technical data sheet

Cover with chequer plate and turn buckle FS

Item number: 6049183

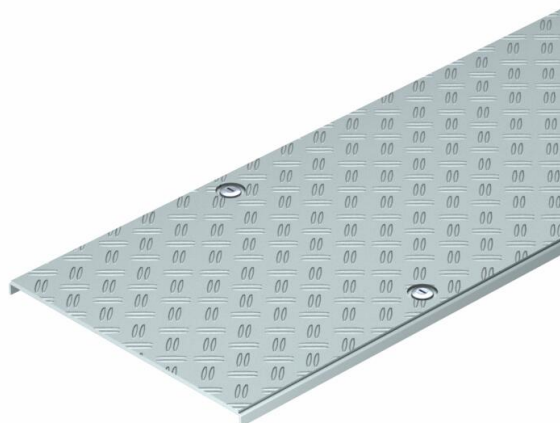

Cable tray cover for the walkable BKRS cable tray system. The basic cover is strip galvanised in a material thickness of 2 mm with additional aluminium chequer riveted on in a thickness of 4 mm, sturdy and non-slip. Turn buckle fastening with a turn buckle distance of 500 mm.

When the cover is used under wind, draught or pressure impacts, additional security measures are required.

The covers are tested according to DIN 51130 and possess anti-slip class R10 and displacement space class V8.

The turn buckles for cover mounting are pre-installed.



Aluminium/Steel

Master data

Item number	6049183
Description 1	Cover with chequer plate
Description 2	Sash lock spacing 500 mm
Manufacturer	OBO
Dimension	200x3000
Colour	aluminium
Material	Aluminium/Steel
Smallest sales unit	3
Unit of quantity	Metre
Weight	503.67 kg
Weight unit	kg/100 m
CO Footprint (GWP) Cradle-to-Gate	32,6892 kg COe / 1 Meter


Technical data sheet

Cover with chequer plate and turn buckle FS

Item number: 6049183



Dimensions

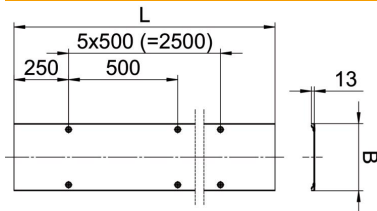

Length	3,000 mm
Length	10 ft
Width	200 mm
Width	8 in
Plate thickness	0.24 in
Plate thickness	6 mm
Dimension B	200 mm
Dimension L	3,000 mm

Technical data

Number of turn buckles	14 St.
Fastening type	Sash lock
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Rustproof steel, pickled	no