


# Technical data sheet

## Cover for mesh cable tray, latchable A2

Item number: 6001862

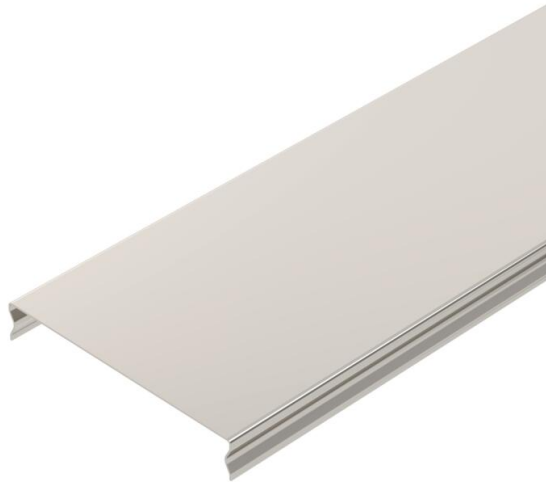

Lockable cover for mesh cable trays of type GR and GRM. Protects cables from damage, contamination and moisture from above. Suitable for the foodstuffs or chemicals industries.

With transverse bead from 400 mm width.

When using covers outdoors, additional measures against the influence of wind may need to be taken.



**A2** Stainless steel

**2B** Bright, treated

### Master data

Item number	6001862
Type	DGRR 100 A2
Description 1	Cover snapable
Description 2	for mesh cable tray
Available from	01.04.2019
Manufacturer	OBO
Dimension	100x3000
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	3
Unit of quantity	Metre
Weight	78.333 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	4,5413 kg CO2e / 1 Meter


# Technical data sheet

Cover for mesh cable tray, latchable A2


Item number: 6001862



## Dimensions

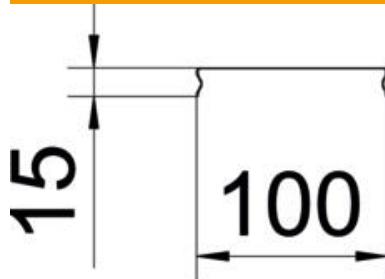

Length	3,000 mm
Width	98 mm
Width	3.86 in
Height	15 mm
Height	0.59 in
Plate thickness	0.8 mm
Dimension B	97 mm

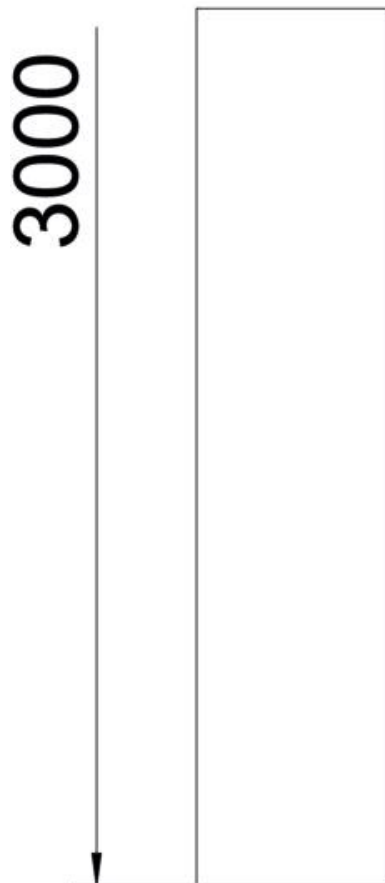

# Technical data sheet

## Cover for mesh cable tray, latchable A2

Item number: 6001862



### Technical data

Fastening type	Locking
Maintain electrical functions	no
Suitable for mesh cable tray	yes
Suitable for cable ladder	no
Suitable for cable tray	no
Rustproof steel, pickled	no