

Technical data sheet

Cover for mesh cable tray, latchable A2

Item number: 6001860



Lockable cover for mesh cable trays of type GR and GRM. Protects cables from damage, contamination and moisture from above. Suitable for the foodstuffs or chemicals industries.

With transverse bead from 400 mm width.

When using covers outdoors, additional measures against the influence of wind may need to be taken.



A2	Stainless steel
2B	Bright, treated

Master data

Item number	6001860
Type	DGRR 50 A2
Description 1	Cover snapable
Description 2	for mesh cable tray
Available from	01.04.2019
Manufacturer	OBO
Dimension	50x3000
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	3
Unit of quantity	Metre
Weight	47.333 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	3,2494 kg CO2e / 1 Meter


Technical data sheet

Cover for mesh cable tray, latchable A2


Item number: 6001860



Dimensions

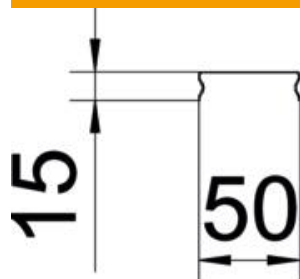

Length	3,000 mm
Width	50 mm
Width	1.97 in
Height	15 mm
Height	0.59 in
Plate thickness	0.8 mm
Dimension B	50 mm

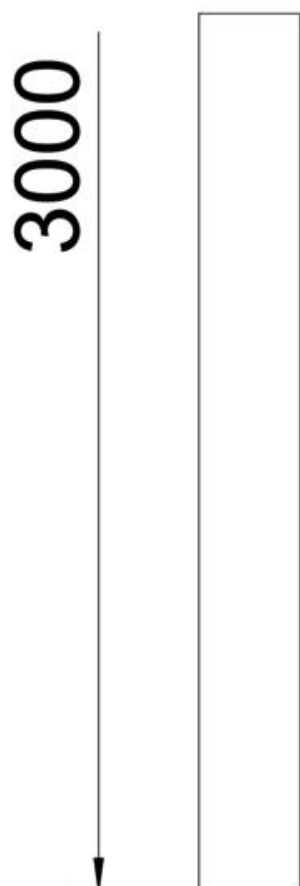

Technical data sheet

Cover for mesh cable tray, latchable A2

Item number: 6001860



Technical data

Fastening type	Locking
Maintain electrical functions	no
Suitable for mesh cable tray	yes
Suitable for cable ladder	no
Suitable for cable tray	no
Rustproof steel, pickled	no