


Technical data sheet

Cover for mesh cable tray, latchable A2

Item number: 6001874

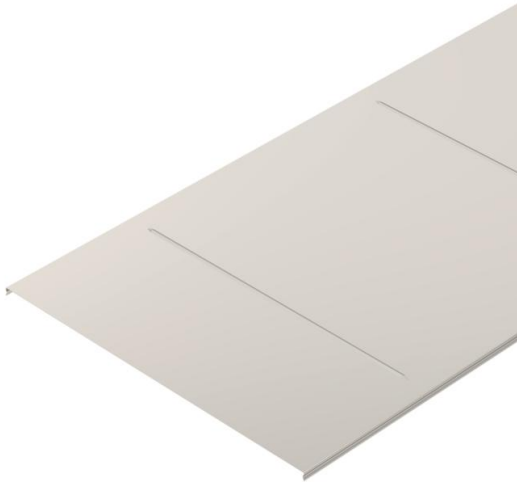

Lockable cover for mesh cable trays of type GR and GRM. Protects cables from damage, contamination and moisture from above. Suitable for the foodstuffs or chemicals industries.

With transverse bead from 400 mm width.

When using covers outdoors, additional measures against the influence of wind may need to be taken.



A2	Stainless steel
2B	Bright, treated

Master data

Item number	6001874
Type	DGRR 600 A2
Description 1	Cover snapable
Description 2	for mesh cable tray
Available from	01.04.2019
Manufacturer	OBO
Dimension	600x3000
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	3
Unit of quantity	Metre
Weight	393.333 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	22,5408 kg CO2e / 1 Meter


Technical data sheet

Cover for mesh cable tray, latchable A2

Item number: 6001874



Dimensions

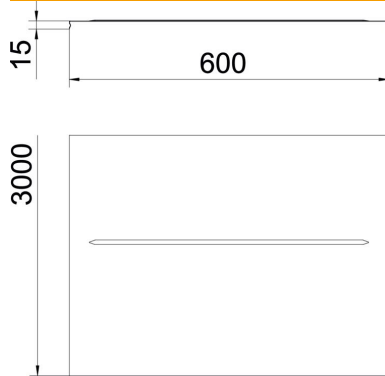

Length	3,000 mm
Width	598 mm
Width	23.54 in
Height	15 mm
Height	0.59 in
Plate thickness	0.8 mm
Dimension B	598 mm

Technical data

Fastening type	Locking
Maintain electrical functions	no
Suitable for mesh cable tray	yes
Suitable for cable ladder	no
Suitable for cable tray	no
Rustproof steel, pickled	no