


# Technical data sheet

## Cover for mesh cable tray, latchable FT

Item number: 6001834

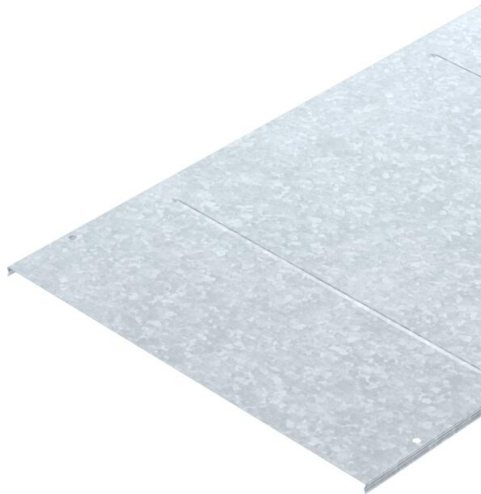

Lockable cover for mesh cable trays of type GR and GRM. Protects cables from damage, contamination and moisture from above. Suitable for industrial areas such as mechanical engineering.  
With transverse bead from 400 mm width.  
When using covers outdoors, additional measures against the influence of wind may need to be taken.



|           |                    |
|-----------|--------------------|
| <b>St</b> | Steel              |
| <b>FT</b> | Hot-dip galvanised |

### Master data

|                                    |                           |
|------------------------------------|---------------------------|
| Item number                        | 6001834                   |
| Type                               | DGRR 600 FT               |
| Description 1                      | Cover snapable            |
| Description 2                      | for mesh cable tray       |
| Available from                     | 01.04.2019                |
| Manufacturer                       | OBO                       |
| Dimension                          | 600x3000                  |
| Colour                             | zinc                      |
| Material                           | Steel                     |
| Surface                            | Hot-dip galvanised        |
| Surface standard                   | DIN EN ISO 1461           |
| Smallest sales unit                | 3                         |
| Unit of quantity                   | Metre                     |
| Weight                             | 418 kg                    |
| Weight unit                        | kg/100 m                  |
| CO2 Footprint (GWP) Cradle-to-Gate | 10,8221 kg CO2e / 1 Meter |


# Technical data sheet

## Cover for mesh cable tray, latchable FT

Item number: 6001834



### Dimensions

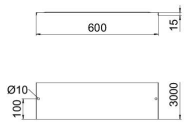

|                 |          |
|-----------------|----------|
| Length          | 3,000 mm |
| Width           | 598 mm   |
| Width           | 23.54 in |
| Height          | 15 mm    |
| Height          | 0.59 in  |
| Plate thickness | 0.75 mm  |
| Dimension B     | 598 mm   |

### Technical data

|                               |         |
|-------------------------------|---------|
| Fastening type                | Locking |
| Maintain electrical functions | no      |
| Suitable for mesh cable tray  | yes     |
| Suitable for cable ladder     | no      |
| Suitable for cable tray       | no      |
| Rustproof steel, pickled      | no      |