

Technical data sheet

Double clamp, fitting mounting A2

Item number: 6035998



Double clamp to mount fittings on lockable or screw-on cable trays.



A2	Stainless steel
2B	Bright, treated

Master data

Item number	6035998
Type	DOP A2
Description 1	Double clamp
Description 2	for fastening of fittings
Manufacturer	OBO
Dimension	42x13x13
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.325 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0178 kg CO2e / 1 Piece


Technical data sheet

Double clamp, fitting mounting A2

Item number: 6035998



Dimensions

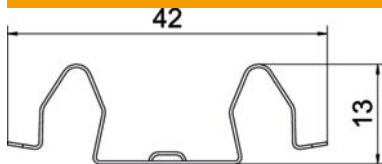

Length	42 mm
Width	13 mm
Height	13 mm



Technical data

Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Suitable for profile shapes	Miscellaneous
Adjustable connector, horizontal	no
Articulated connector, vertical	no
Material thickness	0.4 mm
Profile shape	Miscellaneous
Rustproof steel, pickled	yes
Permitted temperature range, max.	120 °C
Permitted temperature range, min.	-20 °C
Connection type	Screwless connector