

# Technical data sheet

## Unperforated cover A4


Item number: 6052978



Cover for cable trays and mesh cable trays.

Transverse bead from 500 mm width.

When using covers outdoors, additional measures against the influence of wind must be taken.

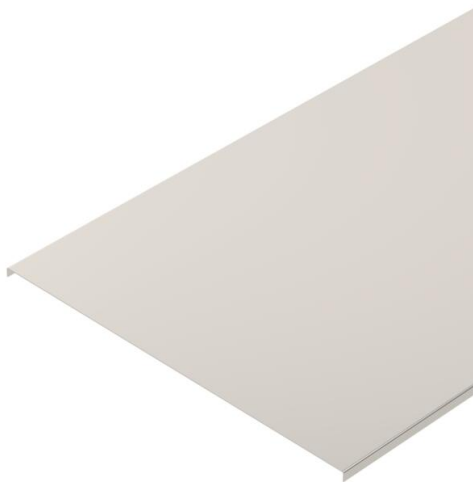

**A4** Stainless steel

**2B** Bright, treated

### Master data

Item number	6052978
Type	DRLU 050 A4
Description 1	Unperforated cover
Description 2	for cable tray and ladder
Manufacturer	OBO
Dimension	50x3000
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	3
Unit of quantity	Metre
Weight	59.767 kg
Weight unit	kg/100 m


# Technical data sheet

## Unperforated cover A4

Item number: 6052978



### Dimensions

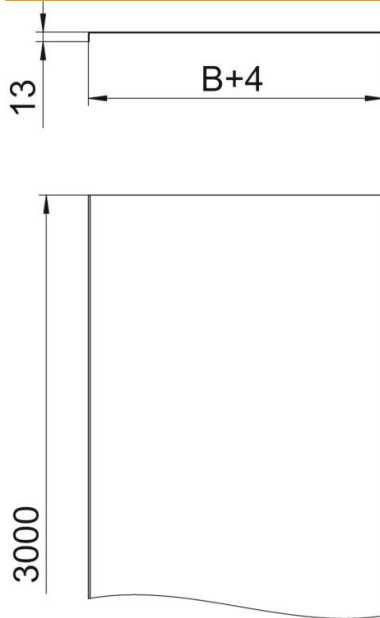

Length	3,000 mm
Length	10 ft
Width	50 mm
Width	2 in
Height	13 mm
Plate thickness	0.04 in
Plate thickness	1 mm
Dimension B	50 mm

### Technical data

Fastening type	Cover clamp
Maintain electrical functions	no
Suitable for mesh cable tray	yes
Suitable for cable ladder	yes
Suitable for cable tray	yes
Rustproof steel, pickled	no