


Technical data sheet

Unperforated cover A2

Item number: 6052824

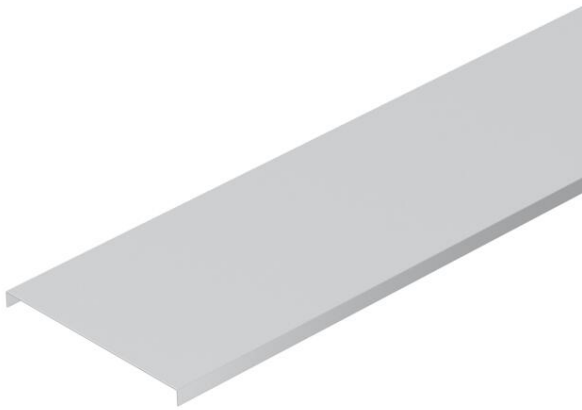

Cover for cable trays and mesh cable trays.
Transverse bead from 500 mm width.
When using covers outdoors, additional measures against the influence of wind must be taken.



A2 Stainless steel

2B Bright, treated

Master data

Item number	6052824
Description 1	Unperforated cover
Description 2	for cable tray and ladder
Manufacturer	OBO
Dimension	100x3000
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	3
Unit of quantity	Metre
Weight	99 kg
Weight unit	kg/100 m
CO Footprint (GWP) Cradle-to-Gate	4,8546 kg COe / 1 Meter


Technical data sheet

Unperforated cover A2

Item number: 6052824



Dimensions

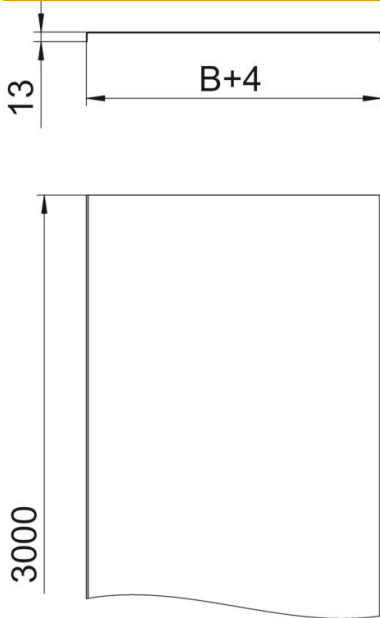

Length	3,000 mm
Length	10 ft
Width	100 mm
Width	4 in
Height	35 mm
Plate thickness	0.04 in
Plate thickness	1 mm
Dimension B	100 mm
Dimension H	15 mm

Technical data

Fastening type	Cover clamp
Maintain electrical functions	no
Suitable for mesh cable tray	yes
Suitable for cable ladder	yes
Suitable for cable tray	yes
Rustproof steel, pickled	no