


Technical data sheet

Unperforated cover DD

Item number: 6052647



Cover for cable trays and mesh cable trays.
Transverse bead from 500 mm width.
When using covers outdoors, additional measures against the influence of wind must be taken.

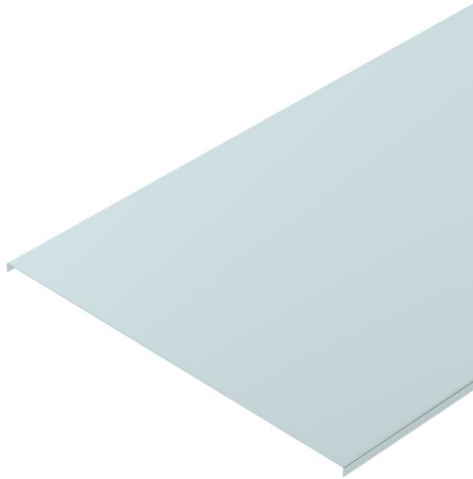

St Steel

DD Strip galvanised zinc/aluminium, Double Dip

Master data

Item number	6052647
Description 1	Unperforated cover
Description 2	for cable tray and ladder
Manufacturer	OBO
Dimension	150x3000
Colour	zinc
Material	Steel
Surface	Strip galvanised zinc/aluminium, Double Dip
Surface standard	DIN EN 10346
Smallest sales unit	3
Unit of quantity	Metre
Weight	138.267 kg
Weight unit	kg/100 m
CO Footprint (GWP) Cradle-to-Gate	3,74 kg COe / 1 Meter

Technical data sheet

Unperforated cover DD

Item number: 6052647



Dimensions



Length	3,000 mm
Length	10 ft
Width	150 mm
Width	6 in
Height	13 mm
Plate thickness	0.04 in
Plate thickness	1 mm
Dimension B	150 mm
Dimension H	15 mm

Technical data

Fastening type	Cover clamp
Maintain electrical functions	no
Suitable for mesh cable tray	yes
Suitable for cable ladder	yes
Suitable for cable tray	yes
Rustproof steel, pickled	no