


Technical data sheet

Unperforated cover DD

Item number: 6052650

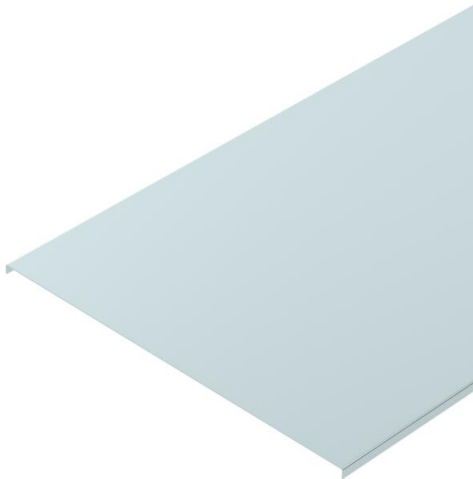

Cover for cable trays and mesh cable trays.
Transverse bead from 500 mm width.
When using covers outdoors, additional measures against the influence of wind must be taken.



- St** Steel
- DD** Strip galvanised zinc/aluminium, Double Dip

Master data	
Item number	6052650
Description 1	Unperforated cover
Description 2	for cable tray and ladder
Manufacturer	OBO
Dimension	200x3000
Colour	zinc
Material	Steel
Surface	Strip galvanised zinc/aluminium, Double Dip
Surface standard	DIN EN 10346
Smallest sales unit	3
Unit of quantity	Metre
Weight	177.5 kg
Weight unit	kg/100 m
CO Footprint (GWP) Cradle-to-Gate	4,7771 kg COe / 1 Meter

Technical data sheet

Unperforated cover DD

Item number: 6052650



Dimensions



Length	3,000 mm
Length	10 ft
Width	200 mm
Width	8 in
Height	13 mm
Plate thickness	0.04 in
Plate thickness	1 mm
Dimension B	200 mm
Dimension H	15 mm

Technical data

Fastening type	Cover clamp
Maintain electrical functions	no
Suitable for mesh cable tray	yes
Suitable for cable ladder	yes
Suitable for cable tray	yes
Rustproof steel, pickled	no