


# Technical data sheet

## Unperforated cover A2

Item number: 6052837

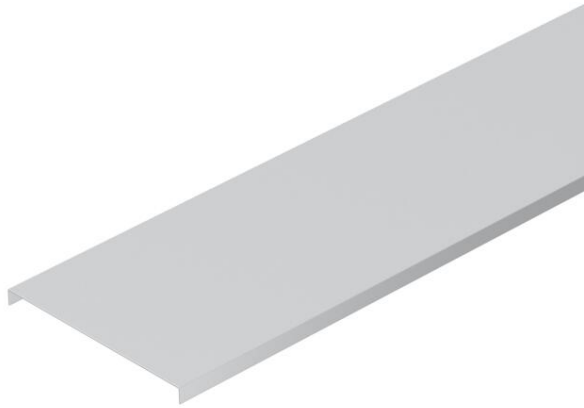

Cover for cable trays and mesh cable trays.

Transverse bead from 500 mm width.

When using covers outdoors, additional measures against the influence of wind must be taken.



**A2** Stainless steel

**2B** Bright, treated

### Master data

|                     |                           |
|---------------------|---------------------------|
| Item number         | 6052837                   |
| Description 1       | Unperforated cover        |
| Description 2       | for cable tray and ladder |
| Manufacturer        | OBO                       |
| Dimension           | 400x3000                  |
| Colour              | stainless steel           |
| Material            | Stainless steel           |
| Surface             | Bright, treated           |
| Surface standard    |                           |
| Smallest sales unit | 3                         |
| Unit of quantity    | Metre                     |
| Weight              | 334.5 kg                  |
| Weight unit         | kg/100 m                  |

# Technical data sheet

## Unperforated cover A2

Item number: 6052837



### Dimensions



|                 |          |
|-----------------|----------|
| Length          | 3,000 mm |
| Length          | 10 ft    |
| Width           | 400 mm   |
| Width           | 16 in    |
| Height          | 35 mm    |
| Plate thickness | 0.04 in  |
| Plate thickness | 1 mm     |
| Dimension B     | 400 mm   |
| Dimension H     | 15 mm    |

### Technical data

|                               |             |
|-------------------------------|-------------|
| Fastening type                | Cover clamp |
| Maintain electrical functions | no          |
| Suitable for mesh cable tray  | yes         |
| Suitable for cable ladder     | yes         |
| Suitable for cable tray       | yes         |
| Rustproof steel, pickled      | no          |