


Technical data sheet

Cover with turn buckle FT SOMY

Item number: 7196034



Cover for cable trays and cable ladders with three pairs of turn buckles.
When using covers outdoors, additional measures against the influence of wind must be taken.

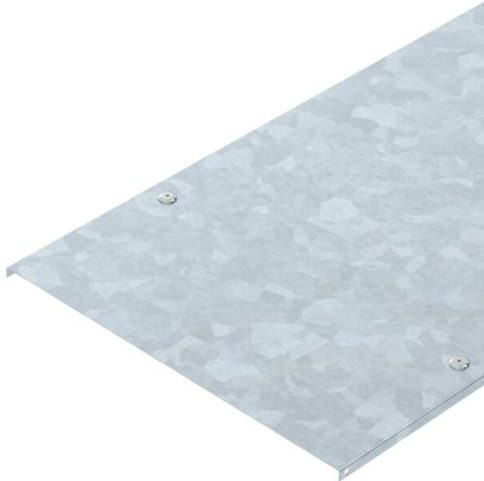

St

Steel

FT
SO

Hot-dip galvanised 85 µm

Master data

| | |
|---------------------|---------------------------|
| Item number | 7196034 |
| Type | DRL 150 FT SO |
| Description 1 | Cover with turn buckle |
| Description 2 | for cable tray and ladder |
| Manufacturer | OBO |
| Dimension | 150x3000 |
| Colour | zinc |
| Material | Steel |
| Surface | Hot-dip galvanised 85 µm |
| Surface standard | DIN EN ISO 1461 |
| Smallest sales unit | 3 |
| Unit of quantity | Metre |
| Weight | 165.4 kg |
| Weight unit | kg/100 m |


Technical data sheet

Cover with turn buckle FT SOMY


Item number: 7196034



Dimensions

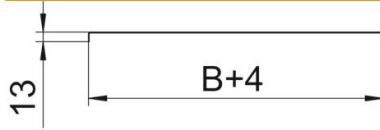

| | |
|-----------------|----------|
| Length | 3,000 mm |
| Height | 13 mm |
| Plate thickness | 1 mm |
| Dimension B | 150 mm |

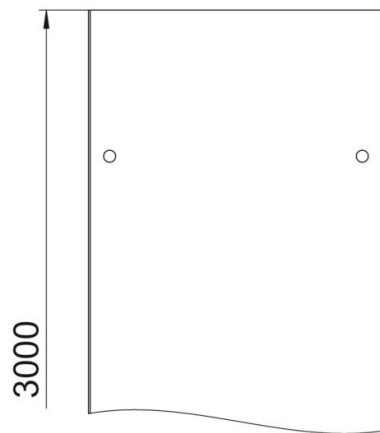

Technical data

| | |
|-------------------------------|-----------|
| Fastening type | Sash lock |
| Maintain electrical functions | no |
| Suitable for mesh cable tray | no |
| Suitable for cable ladder | yes |
| Suitable for cable tray | yes |
| Rustproof steel, pickled | no |