

Technical data sheet

Turn buckle FT

Item number: 6065018



Turn buckle for additional installation or installation at a later date.
Single-sided turn buckle. Use for cover widths of 100–600 mm.
Depending on the cover version, dimension B varies as follows:

DRL / DRLU = 27 mm

DBKR = 27 mm

WDRL = 38 mm

WKLD = 58 mm



St Steel

FT Hot-dip galvanised

Master data

Item number	6065018
Type	DRL H S FT
Description 1	Turn buckle
Description 2	for cover
Manufacturer	OBO
Dimension	Ø20 mm
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	20
Unit of quantity	Piece
Weight	3.15 kg
Weight unit	kg/100 pc.



Technical data sheet

Turn buckle FT

Item number: 6065018



Dimensions

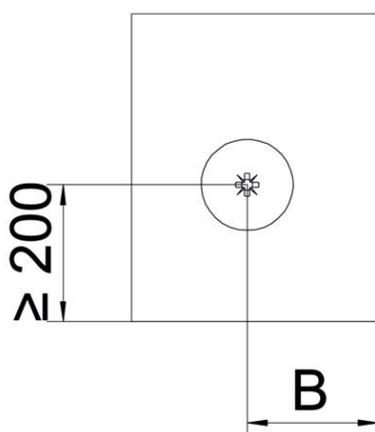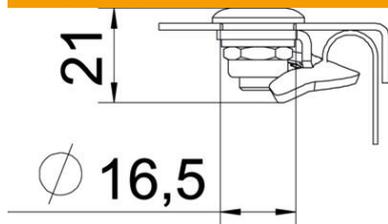

Technical data

Suitable for mesh cable tray	no
Suitable for cable ladder	yes
Suitable for cable tray	yes
Rustproof steel, pickled	no