

# Technical data sheet

Data technology support, 1 module, straight outlet, type C,  
without dust protection slider  
Item number: 6119284



Data technology support with straight outlet and without a locking slider to accept two data technology connection modules with RJ45 socket. The locking fastening is suitable for horizontal and vertical installation in the system environment. Type C has a mounting opening of 19.30 x 14.80 mm and is designed for direct fastening of the data connection modules in the mounting opening.

The type C data technology support (without dust protection slider) is suitable for accepting the following data connection modules: 3M: Volition K6, K10 and Cat. 6A.

For installation in Rapid 45 and Rapid 80 device installation trunking, ISS service poles and underfloor systems.

PC Polycarbonate

## Master data

|                                    |                                |
|------------------------------------|--------------------------------|
| Item number                        | 6119284                        |
| Type                               | DTG-02C AL1                    |
| Description 1                      | Data technology support        |
| Description 2                      | f. 2 connection modules type C |
| Manufacturer                       | OBO                            |
| Dimension                          | 45x45mm                        |
| Colour                             | Aluminium painted              |
| Material                           | Polycarbonate                  |
| Smallest sales unit                | 1                              |
| Unit of quantity                   | Piece                          |
| Weight                             | 1.383 kg                       |
| Weight unit                        | kg/100 pc.                     |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,1603 kg CO2e / 1 Piece       |


# Technical data sheet

Data technology support, 1 module, straight outlet, type C,  
without dust protection slider


Item number: 6119284



## Dimensions

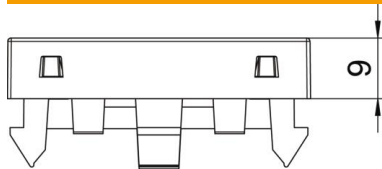

|        |       |
|--------|-------|
| Width  | 45 mm |
| Height | 45 mm |

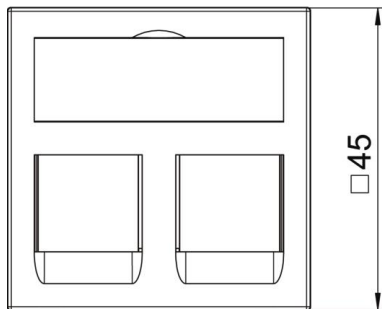

## Technical data

|                      |  |
|----------------------|--|
| Surface version      | Matt                                   |
| Fastening type       | Lock                                   |
| Labelling panel      | With labelling panel                   |
| Halogen-free         | yes                                    |
| Hinged cover         | no                                     |
| Lamp-wire connector  | no                                     |
| With printed label   | no                                     |
| With dust protection | no                                     |
| Mounting opening     | Type C                                 |
| Protection rating    | IP20                                   |
| Depth                | 9 mm                                   |
| Support ring         | no                                     |
| Transparent          | no                                     |
| Use                  | Installable data connector             |
| Strain relief option | no                                     |
| Combination          | Basic element with central cover plate |