

# Technical data sheet

Data technology support, 1 module, slanting outlet, type C,  
without dust protection slider  
Item number: 6119288



Data technology support with slanting outlet and without a locking slider to accept two data technology connection modules with RJ45 socket. The locking fastening is suitable for horizontal and vertical installation in the system environment. Type C has a mounting opening of 19.30 x 14.80 mm and is designed for direct fastening of the data connection modules in the mounting opening. The type C data technology support (without dust protection slider) is suitable for accepting the following data connection modules: 3M: Volition K6, K10 and Cat. 6A. For installation in Rapid 45 and Rapid 80 device installation trunking, ISS service poles and underfloor systems.

PC Polycarbonate

Master data		
Item number	6119288	
Type	DTS-02C SWGR1	
Description 1	Data technology support	
Description 2	f. 2 connection modules type C	
Manufacturer	OBO	
Dimension	45x45mm	
Colour	Black-grey; RAL 7021	
Material	Polycarbonate	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	1.4 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,162 kg CO2e / 1 Piece	


# Technical data sheet

Data technology support, 1 module, slanting outlet, type C,  
without dust protection slider


Item number: 6119288



## Dimensions

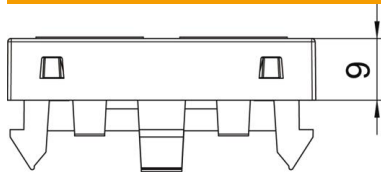

Width	45 mm
Height	45 mm

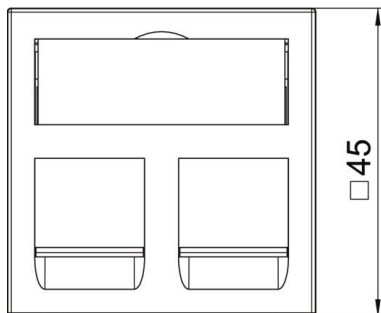

## Technical data

Number of units	1
Surface version	Matt
Fastening type	Lock
Labelling panel	With labelling panel
Halogen-free	yes
Hinged cover	no
Lamp-wire connector	no
With printed label	no
With dust protection	no
Mounting opening	Type C
Protection rating	IP20
Depth	26 mm
Support ring	no
Transparent	no
Use	Installable data connector
Strain relief option	no
Combination	Basic element with central cover plate