

# Technical data sheet

## Data technology support, 1 module, slanting outlet, type EP

Item number: 6119268



Data technology support with slanting outlet and locking slider to accept two data technology connection modules with RJ45 socket. The locking fastening is suitable for horizontal and vertical installation in the system environment. Type EP has a special module seat and is designed for indirect fastening of the data connection modules in the mounting opening.

The type EP data technology support is suitable for accepting the following data connection modules: Leoni Kerpen: MegaLine-Connect45 ELine.  
For installation in Rapid 45 and Rapid 80 device installation trunking, ISS service poles and underfloor systems.

**PC** Polycarbonate

### Master data

|                                    |                                |
|------------------------------------|--------------------------------|
| Item number                        | 6119268                        |
| Type                               | DTS-2EP RW1                    |
| Description 1                      | Data technology support        |
| Description 2                      | f.2 connection modules type EP |
| Manufacturer                       | OBO                            |
| Dimension                          | 45x45mm                        |
| Colour                             | Pure white; RAL 9010           |
| Material                           | Polycarbonate                  |
| Smallest sales unit                | 1                              |
| Unit of quantity                   | Piece                          |
| Weight                             | 1.5 kg                         |
| Weight unit                        | kg/100 pc.                     |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,2309 kg CO2e / 1 Piece       |


# Technical data sheet

Data technology support, 1 module, slanting outlet, type EP

Item number: 6119268



## Dimensions

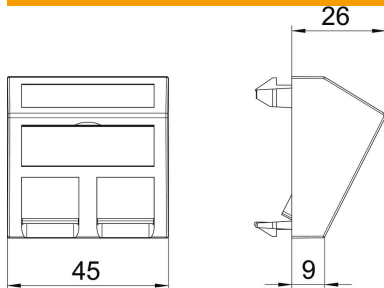

|        |       |
|--------|-------|
| Width  | 45 mm |
| Height | 45 mm |

## Technical data

|                      |  |
|----------------------|--|
| Number of units      | 1                                      |
| Surface version      | Matt                                   |
| Fastening type       | Lock                                   |
| Labelling panel      | With labelling panel                   |
| Halogen-free         | yes                                    |
| Hinged cover         | no                                     |
| Lamp-wire connector  | no                                     |
| With printed label   | no                                     |
| With dust protection | yes                                    |
| Mounting opening     | Type EP                                |
| Protection rating    | IP20                                   |
| Depth                | 26 mm                                  |
| Support ring         | no                                     |
| Transparent          | no                                     |
| Use                  | Installable data connector             |
| Strain relief option | no                                     |
| Combination          | Basic element with central cover plate |