

Technical data sheet

Data technology support, 1 module, slanting outlet, type RM

Item number: 6119302



Data technology support with slanting outlet and locking slider to accept two data technology connection modules with RJ45 socket. The locking fastening is suitable for horizontal and vertical installation in the system environment. Type RM has a special module seat and is designed for indirect fastening of the data connection modules in the mounting opening.

The type RM data technology support is suitable for accepting the following data connection modules: Types ASM-C5, ASM-C5 G, ASM-C6 and ASM-C6 G; R&M: Cat. 5 and Cat. 6 modules without support plate.

For installation in Rapid 45 and Rapid 80 device installation trunking, ISS service poles and underfloor systems.

PC Polycarbonate

| Master data | | |
|---------------------|--------------------------------|--|
| Item number | 6119302 | |
| Description 1 | Data technology support | |
| Description 2 | f.2 connection modules type RM | |
| Manufacturer | OBO | |
| Dimension | 45x45mm | |
| Colour | Aluminium painted | |
| Material | Polycarbonate | |
| Smallest sales unit | 1 | |
| Unit of quantity | Piece | |
| Weight | 2.9 kg | |
| Weight unit | kg/100 pc. | |


Technical data sheet

Data technology support, 1 module, slanting outlet, type RM

Item number: 6119302



Dimensions

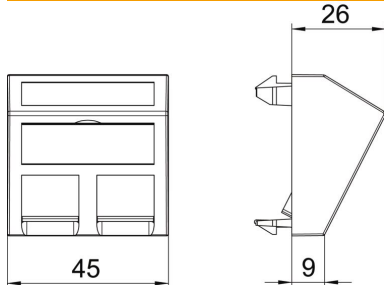

| | |
|--------|-------|
| Width | 45 mm |
| Height | 45 mm |

Technical data

| | |
|----------------------|--|
| Number of units | 1 |
| Surface version | Matt |
| Fastening type | Lock |
| Labelling panel | With labelling panel |
| Halogen-free | yes |
| Hinged cover | no |
| Lamp-wire connector | no |
| With printed label | no |
| With dust protection | yes |
| Mounting opening | Type RM |
| Protection rating | IP20 |
| Depth | 26 mm |
| Support ring | no |
| Transparent | no |
| Use | Installable data connector |
| Strain relief option | no |
| Combination | Basic element with central cover plate |