

Technical data sheet

Plug-in seal EDVS, light grey

Item number: 2012383



The push-in nipple can be cut back to suit the relevant cable diameter.

M


FLOORING
WALDNER


CEUK
CA


IP
54

M

EVA

Ethylene vinyl acetate

Master data		
Item number	2012383	
Type	EDVS M25 LGR	
Description 1	Plug-in seal	
Manufacturer	OBO	
Dimension	M25	
Colour	Light grey; RAL 7035	
Material	Ethylene vinyl acetate	
Smallest sales unit	100	
Unit of quantity	Piece	
Weight	0.179 kg	
Weight unit	kg/100 pc.	
CO Footprint (GWP) Cradle-to-Gate	0,0165 kg COe / 1 Piece	


Technical data sheet

Plug-in seal EDVS, light grey

Item number: 2012383



Dimensions

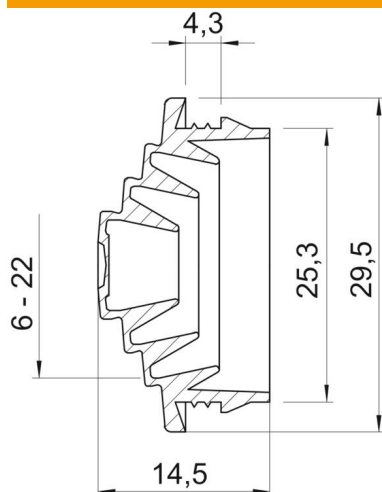

Dimension A	4.3 mm
Dimension D1	29.5 mm
Dimension D2	25.3 mm
Dimension D3	6 mm
Dimension D4	10 mm
Dimension D5	15 mm
Dimension D6	20
Dimension D7	22
Dimension L	14.5 mm
Dimension t	4.3 mm

Technical data

Version for	Cuttable
Flame-resistant	acc. to VDE 0471/DIN 695 Part 2-1, test temperature 650°C
for diameter, max.	22 mm
for diameter, min.	0 mm
for wall thickness, max.	4.3
for wall thickness, min.	3.9
Size	M25
Halogen-free	yes
Nominal diameter	25 mm
Protection rating	IP54