

Technical data sheet

Flat-head screw with hexalobular internal G

Item number: 6049246



Flat-head screw with hexalobular internal to connect base and crossbeam of the symmetrical floor support BSS, to be used on walkable cable tray system BKRS.



St	Steel
G	Electrogalvanized

Master data

Item number	6049246
Type	FKS 6x12 G
Description 1	Flat head screw
Description 2	with hexagon socket
Manufacturer	OBO
Dimension	M6x12
Colour	zinc
Material	Steel
Surface	Electrogalvanized
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.53 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,013 kg CO2e / 1 Piece


Technical data sheet

Flat-head screw with hexalobular internal G

Item number: 6049246



Dimensions

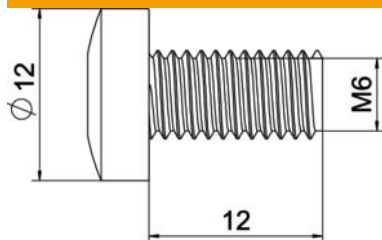

Dimension	M6x12
Length	12.6 mm
Width	12 mm
Dimension D	12 mm
Dimension L	12 mm

Technical data

Resistance grade	8.8
Thread	M6
Thread metric	6
Thread type	Metric
Thread length	12 mm
Fibre-glass reinforced	no
Halogen-free	yes
Head diameter	12 mm
Head shape	Flat head
Head shape	Flat head
With flange	no
With nut	no
With washer	no
Rustproof steel, pickled	no
Shank length	12
Impact-resistant	no
Screw system	Torx
Self-locking	no
Full thread	yes
Left thread	no
Thread, imperial	1/4"