

Technical data sheet

Truss-head bolt with flange nut G

Item number: 6406133



Hot galvanised truss-head bolt with square neck including electrogalvanised combination nut.
For universal fastening of construction components. Permitted use of the article only in dry atmospheres.




St	Steel
G	Electrogalvanized

Master data

Item number	6406133
Description 1	Truss-head bolt
Description 2	with combination nut
Manufacturer	OBO
Dimension	M6x12
Colour	zinc
Material	Steel
Surface	Electrogalvanized
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.7 kg
Weight unit	kg/100 pc.

Dimensions

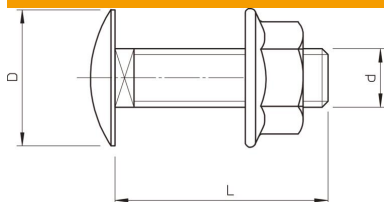

Length	12 mm
Dimension D	13.5 mm
Dimension d	6 mm
Dimension L	12 mm

Technical data sheet

Truss-head bolt with flange nut G

Item number: 6406133



Technical data

Resistance grade	5.6
Thread metric	6
With nut	yes
WAF	10