

Technical data sheet

Truss-head bolt with flange nut F

Item number: 6406157



Truss-head bolt with square neck including flange nut.
For example, for use in longitudinal hole 7 x 20 mm or 7 x 32 mm.




St	Steel
F	Hot galvanized

Master data

Item number	6406157
Description 1	Truss-head bolt
Description 2	with combination nut
Manufacturer	OBO
Dimension	M6x16
Colour	zinc
Material	Steel
Surface	Hot galvanized
Surface standard	DIN 267, Teil 10
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.89 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0104 kg COe / 1 Piece

Dimensions

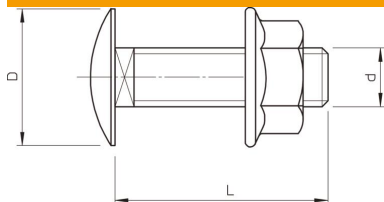

Length	16 mm
Dimension D	13.5 mm
Dimension d	6 mm
Dimension L	16 mm

Technical data sheet

Truss-head bolt with flange nut F

Item number: 6406157



Technical data

Resistance grade	5.6
Thread metric	6
With nut	yes
WAF	10