


Technical data sheet

Truss-head bolt with combination nut, V2A

Item number: 3175608



Truss-head bolt with square neck and combination nut.

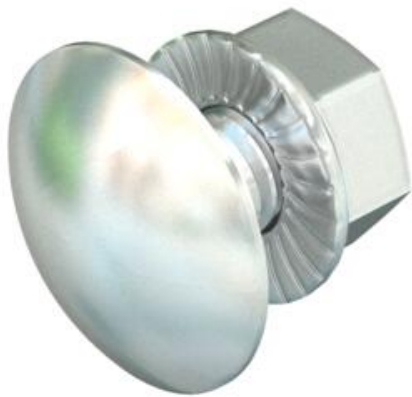

- A2 Stainless steel
- 2B Bright, treated

Master data		
Item number	3175608	
Type	FRSB M8x35 A2	
Description 1	Truss-head bolt	
Description 2	with combination nut	
Manufacturer	OBO	
Dimension	M8x35/35mm	
Material	Stainless steel	
Surface	Bright, treated	
Surface standard		
Smallest sales unit	50	
Unit of quantity	Piece	
Weight	2.57 kg	
Weight unit	kg/100 pc.	
CO Footprint (GWP) Cradle-to-Gate	0,131 kg COe / 1 Piece	


Technical data sheet

Truss-head bolt with combination nut, V2A

Item number: 3175608



Dimensions

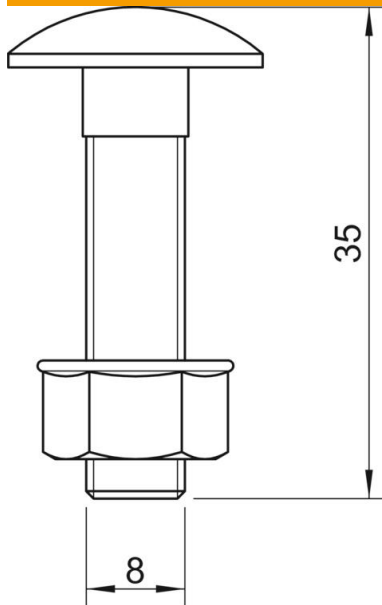

Length	35 mm
Dimension D	8 mm
Dimension L	35 mm

Technical data

Thread metric	8
Thread type	Metric
Head shape	Flat round head with square
With flange	no
With nut	yes
With washer	no
Screw system	Miscellaneous
Self-locking	no
Full thread	yes
Left thread	no