


Technical data sheet

Truss-head bolt with nut and washer F

Item number: 6407471

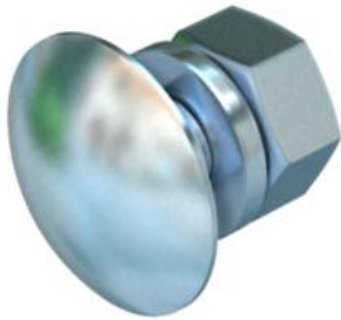

Truss-head bolt with square neck including hexagonal nut and washer.
The truss-head bolt can be used in combination with hot-dip and double-dip galvanized articles.



St

Steel


F

Hot galvanized

Master data

| | |
|---------------------|---------------------|
| Item number | 6407471 |
| Description 1 | Truss-head bolt |
| Description 2 | with washer and nut |
| Manufacturer | OBO |
| Dimension | M10x20 |
| Colour | zinc |
| Material | Steel |
| Surface | Hot galvanized |
| Surface standard | DIN 267, Teil 10 |
| Smallest sales unit | 50 |
| Unit of quantity | Piece |
| Weight | 4.1 kg |
| Weight unit | kg/100 pc. |

Dimensions

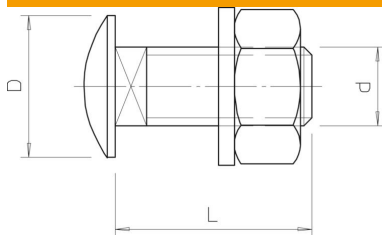

| | |
|-------------|-------|
| Length | 20 mm |
| Dimension D | 24 mm |
| Dimension d | 10 mm |
| Dimension L | 20 mm |

Technical data sheet

Truss-head bolt with nut and washer F

Item number: 6407471



Technical data

| | |
|------------------|-----|
| Resistance grade | 8.8 |
| Thread metric | 10 |
| With nut | yes |
| WAF | 17 |