

# Technical data sheet

## Truss-head bolt with combination nut G

Item number: 6407521



Truss-head bolt with square neck including combination nut.




|    |                   |
|----|-------------------|
| St | Steel             |
| G  | Electrogalvanized |

### Master data

|                     |                            |
|---------------------|----------------------------|
| Item number         | 6407521                    |
| Description 1       | Truss-head bolt            |
| Description 2       | with combination nut       |
| Manufacturer        | OBO                        |
| Dimension           | M10x25                     |
| Colour              | zinc                       |
| Material            | Steel                      |
| Surface             | Electrogalvanized          |
| Surface standard    | EN ISO 19598 / EN ISO 4042 |
| Smallest sales unit | 50                         |
| Unit of quantity    | Piece                      |
| Weight              | 3.926 kg                   |
| Weight unit         | kg/100 pc.                 |

### Dimensions

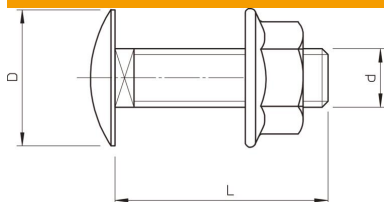

|             |       |
|-------------|-------|
| Length      | 25 mm |
| Dimension D | 24 mm |
| Dimension d | 10 mm |
| Dimension L | 25 mm |

# Technical data sheet

## Truss-head bolt with combination nut G

Item number: 6407521



### Technical data

|                  |     |
|------------------|-----|
| Resistance grade | 8.8 |
| With nut         | yes |