


Technical data sheet

Joint cover, trunking height 70 mm

Item number: 6279772



Joint cover to hide sawn trunking joint edges.

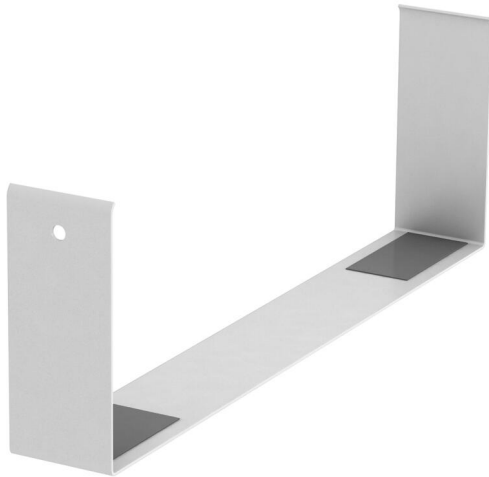

St

Steel

Master data

Item number	6279772
Description 1	Joint cover
Manufacturer	OBO
Dimension	70x210x30mm
Colour	Pure white; RAL 9010
Material	Steel
Smallest sales unit	1
Unit of quantity	Piece
Weight	6.7 kg
Weight unit	kg/100 pc.


Technical data sheet

Joint cover, trunking height 70 mm

Item number: 6279772



Dimensions

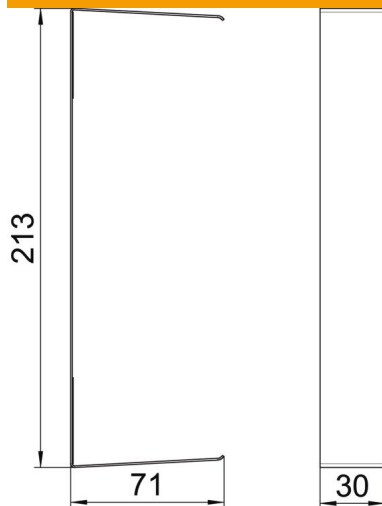

Length	30 mm
Width	213 mm
Height	71 mm

Technical data

Version for	Trunking cut cover
Fastening type	Self-adhesive
Shape	Universal
for duct dimension	70x210
for duct width	210 mm
for trunking height	70 mm
Halogen-free	yes
Duct height, min.	70 mm
Trunking depth	70 mm
Cover width	76.5 mm
Protection rating	IP30
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C