

Technical data sheet

Joint cover, trunking height 90 mm

Item number: 6279776



Joint cover to hide sawn trunking joint edges.



St Steel

Master data

Item number	6279776
Type	G-SVS90110RW
Description 1	Joint cover
Manufacturer	OBO
Dimension	90x110x30mm
Colour	Pure white; RAL 9010
Material	Steel
Smallest sales unit	1
Unit of quantity	Piece
Weight	5.6 kg
Weight unit	kg/100 pc.


Technical data sheet

Joint cover, trunking height 90 mm

Item number: 6279776



Dimensions

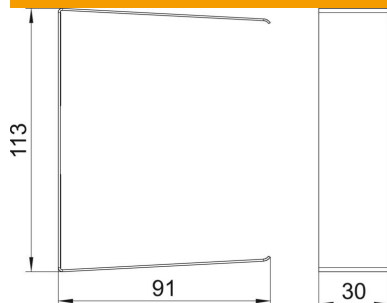

Length	30 mm
Width	113 mm
Height	91 mm

Technical data

Version for	Trunking cut cover
Fastening type	Self-adhesive
Shape	Universal
for duct dimension	90x110
for duct width	110 mm
for trunking height	90 mm
Halogen-free	yes
Duct height, min.	90 mm
Trunking depth	90 mm
Cover width	76.5 mm
Protection rating	IP30
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C