

Technical data sheet

Coupling GA-KUP90

Item number: 6279704



Joint connector for connecting the bases of Rapid 80 GA aluminium device installation trunking.

The scope of delivery of a coupling includes 2 connection plates.



A2 Stainless steel

Master data	
Item number	6279704
Description 1	Coupling
Description 2	univ., for trunking depth 90
Manufacturer	OBO
Dimension	84x120
Colour	stainless steel
Material	Stainless steel
Smallest sales unit	1
Unit of quantity	Packaging unit
Weight	8.2 kg
Weight unit	kg/100 PUs


Technical data sheet

Coupling GA-KUP90

Item number: 6279704



Dimensions

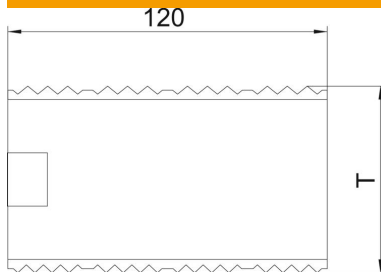

Length	120 mm
Width	84 mm

Technical data

Version for	Universal
Type	coupling
Halogen-free	yes
Trunking depth	90 mm
With equipotential bonding	yes
Protection rating	IP30
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C