


# Technical data sheet

## Trunking cover, aluminium, 100 mm

Item number: 6279733

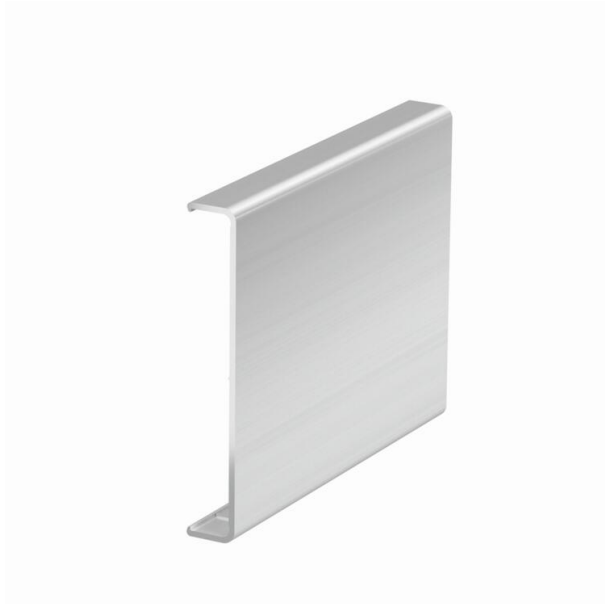

Aluminium cover, for closing Rapid GA device installation trunking and ISS service poles with a 76.5 mm system opening. The firm position of the cover and electrical contact to the lower part of the trunking and service pole is guaranteed thanks to type RKV3V locking brackets. There are 2 pre-mounted locking brackets included per delivery length (100 mm).



Alu	Aluminium
EL	Anodised

### Master data

Item number	6279733
Type	GA-OTEL 100
Description 1	Cover
Manufacturer	OBO
Dimension	12x76,5x100
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	3.83 kg
Weight unit	kg/100 pc.


# Technical data sheet

Trunking cover, aluminium, 100 mm

Item number: 6279733



## Dimensions

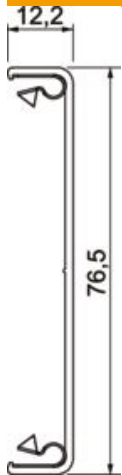

Length	100 mm
Width	76.5 mm
Height	12 mm

## Technical data

Version for	Smooth
Halogen-free	yes
Cover mounting type	Internal
Protection rating	IP30
Protective film	no
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C