

# Technical data sheet

End piece, Style, right

Item number: 6115965



End piece for design device installation trunking of the GAD series. "Style" design version. The end piece can only be used for closing on the right side. Standard version in anodised aluminium, different decoration on request.



|     |           |
|-----|-----------|
| Alu | Aluminium |
| EL  | Anodised  |

## Master data

|                                    |                               |
|------------------------------------|-------------------------------|
| Item number                        | 6115965                       |
| Type                               | GAD ER Style EL               |
| Description 1                      | End piece, Design duct, right |
| Description 2                      | Design Style                  |
| Manufacturer                       | OBO                           |
| Dimension                          | 125x140x37                    |
| Colour                             | aluminium                     |
| Material                           | Aluminium                     |
| Surface                            | Anodised                      |
| Surface standard                   |                               |
| Smallest sales unit                | 1                             |
| Unit of quantity                   | Piece                         |
| Weight                             | 16.2 kg                       |
| Weight unit                        | kg/100 pc.                    |
| CO2 Footprint (GWP) Cradle-to-Gate | 1,8795 kg CO2e / 1 Piece      |


# Technical data sheet

End piece, Style, right

Item number: 6115965



## Dimensions

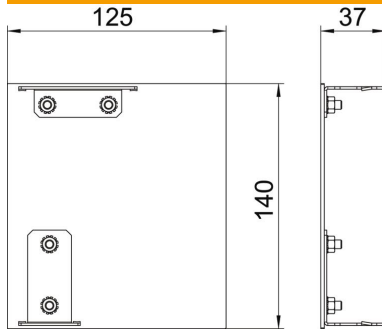

|        |        |
|--------|--------|
| Length | 37 mm  |
| Width  | 140 mm |
| Height | 125 mm |

## Technical data

|                     |              |
|---------------------|--------------|
| Version for         | Asymmetrical |
| Fastening type      | Lockable     |
| for duct width      | 140 mm       |
| for trunking height | 114 mm       |
| Suitable for        | Right        |
| Halogen-free        | yes          |
| Cut lamination      | no           |
| Protective film     | yes          |