


Technical data sheet

Trunking connector and joint cover

Item number: 6116163

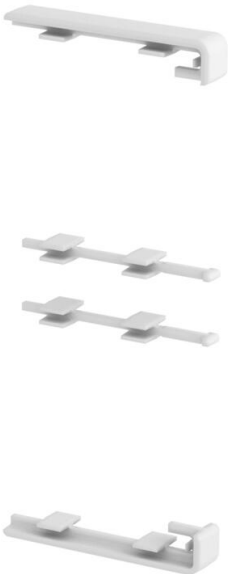

Joint cover for smooth connection of trunking segments.



PVC

 Polyvinylchloride

Master data		
Item number	6116163	
Description 1	Joint cover	
Description 2	for GEK-K53160-3, 3-compart.	
Manufacturer	OBO	
Colour	Pure white; RAL 9010	
Material	Polyvinylchloride	
Smallest sales unit	6	
Unit of quantity	Piece	
Weight	1.324 kg	
Weight unit	kg/100 pc.	


Technical data sheet

Trunking connector and joint cover

Item number: 6116163



Dimensions

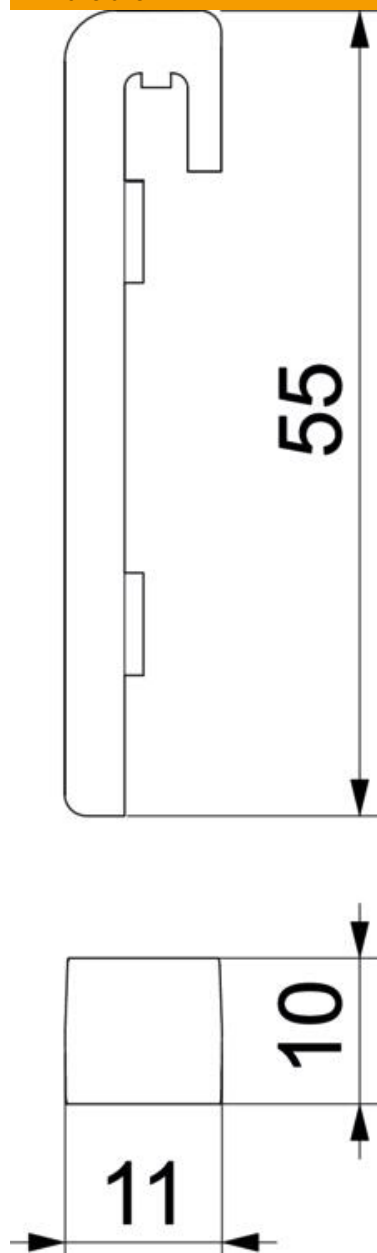

Technical data sheet

Trunking connector and joint cover

Item number: 6116163



Technical data

Version for	Trunking cut cover
Fastening type	Miscellaneous
Shape	Universal
for duct width	165 mm
for trunking height	53 mm
Halogen-free	no
Cover width	45 mm
Protection rating	IP30
Protection rating IK code	IK08
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C