


Technical data sheet

Service outlet - Empty old brass version

Item number: 7405663

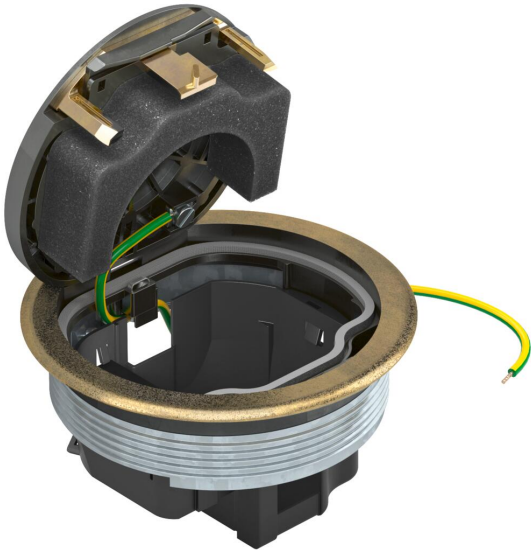

Round installation unit with floor covering protection frame for direct installation in the connection socket UDL2-120. When closed, the installation unit can be wet-cleaned. The minimum installation depth is 70 mm.

Cover plate and socket of the Modul 45 series should be ordered separately.



- Zn

Die-cast zinc
- CuZn  
37

Brass-coated

Master data

Item number	7405663
Type	GESRMS2
Description 1	Service outlet
Description 2	with prot. frame, old brass
Manufacturer	OBO
Dimension	130x130x64
Material	Die-cast zinc
Surface	Brass-coated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	67.965 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,9087 kg CO2e / 1 Piece


# Technical data sheet

## Service outlet - Empty old brass version

Item number: 7405663



### Dimensions

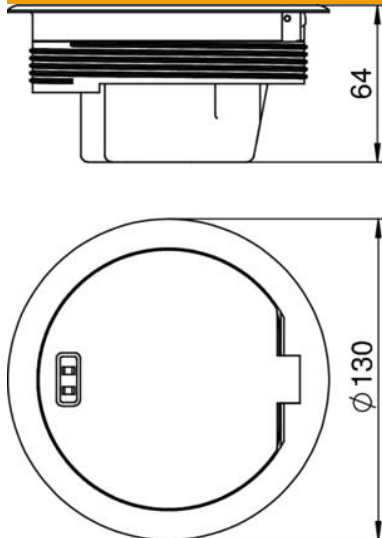

### Technical data

Version for	Round
Floor covering protection frame	yes
Floor care	Wet
Suitable for raised floor installation	no
Suitable for cavity floor installation	no
Suitable for wet care	yes
Suitable for underfloor ducts	yes
With floor covering recess	no
Protection rating (IP) when used	IP20
Protection rating (IP) when unused	IP66
Protection rating IK code	IK10
Opening mechanism	Locking slider