


Technical data sheet

Service outlet - Empty nickel version

Item number: 7405713

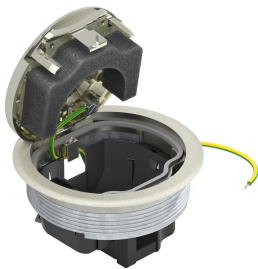

Round installation unit with floor covering protection frame for direct installation in the connection socket UDL2-120 for indoor use. When closed, the installation unit can be wet-cleaned. The minimum installation depth is 70 mm.

Cover plate and socket of the Modul 45 series should be ordered separately.



Zn	Die-cast zinc
N	Nickel-plated

Master data

Item number	7405713
Type	GESRN2
Description 1	Service outlet
Description 2	with prot. frame, Ni-plated
Manufacturer	OBO
Dimension	130x130x64
Material	Die-cast zinc
Surface	Nickel-plated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	67.965 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,9062 kg CO2e / 1 Piece


Technical data sheet

Service outlet - Empty nickel version

Item number: 7405713



Dimensions

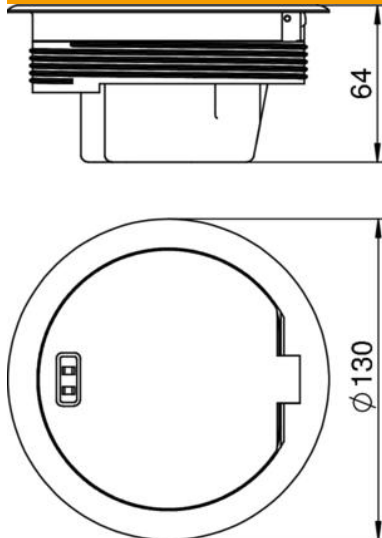

Technical data

Version for	Round
Floor covering protection frame	yes
Floor care	Wet
Suitable for raised floor installation	no
Suitable for cavity floor installation	no
Suitable for wet care	yes
Suitable for underfloor ducts	yes
With floor covering recess	no
Protection rating (IP) when used	IP20
Protection rating (IP) when unused	IP66
Protection rating IK code	IK10
Opening mechanism	Locking slider