

Technical data sheet

Service outlet with blanking cover and Allen slot, GES R2,
nickel-oxidised

Item number: 7408869



Service outlet with blanking cover and Allen slot for GES R2 floor socket for direct installation in the MT R2 installation socket in indoor areas.

The cover version can be used as a cable outlet.

When closed, the floor socket can be wet-cleaned.



Zn	Die-cast zinc
Ni-Ox	nickel-plated oxidized

Master data

Item number	7408869
Description 1	Floor socket
Description 2	blind with Allen key recess
Manufacturer	OBO
Dimension	140 mm
Material	Die-cast zinc
Surface	nickel-plated oxidized
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	58.32 kg
Weight unit	kg/100 pc.


Technical data sheet

Service outlet with blanking cover and Allen slot, GES R2,
nickel-oxidised

Item number: 7408869



Dimensions

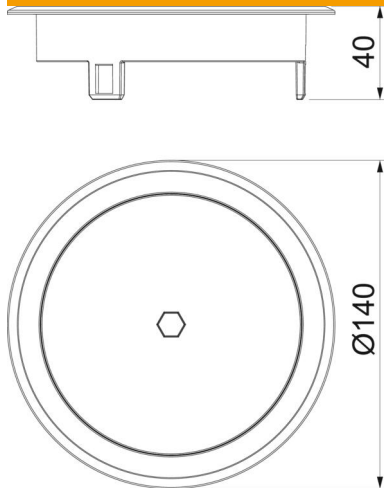

Technical data

Version for	Round
Cable outlet version	No cable outlet
Floor covering protection frame	yes
Floor care	Wet
Suitable for raised floor installation	yes
Suitable for cavity floor installation	yes
Suitable for wet care	yes
Suitable for underfloor ducts	no
With floor covering recess	no
Standard	EN 50085-2-2
Protection rating (IP) when unused	IP66
Protection rating IK code	IK10
Vertical load, large area	to 15,000 N
Vertical load, small area	to 3,000 N
Approvals	VDE
Opening mechanism	Tool